

HIGH PRESSURE PERFORMANCE REDEFINED.



EXEMPLARY WEIGHT SAVINGS

Lighter weight means improved equipment performance and fuel efficiency.



GATES®

MEGASys™

MSHA 2G-11C

ISO 3862 R12, EN 856 R12

Type D, SAE 100R19

Performs above SAE 100R12, Exceeds ISO 18752 Class 280

(19 mm) 4060 psi

28.0 MPa 280 Bar

EXCEPTIONAL FLEXIBILITY

MXG™ 4K offers greater flexibility for easy and reliable installation, so you can use less hose from port to port.




DRIVEN BY POSSIBILITY™




EXTRAORDINARY DURABILITY

XtraTuff™ Plus cover is standard, with 25X abrasion resistance and 800+ hour ozone resistance.

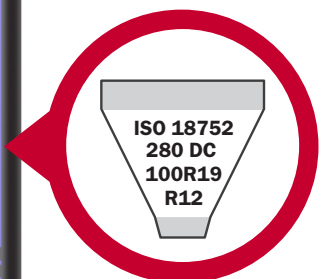

EXTREMELY COMPACT

MXG™ 4K delivers enhanced new wire technology and a slimmer profile for compact areas.

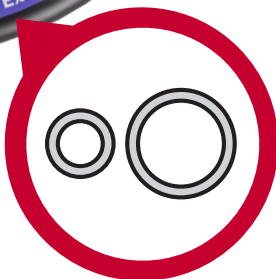

EXTENDED LIFE

Multi-Spec performance qualified to ONE MILLION impulse cycles at 1/2 Minimum Bend Radius.

MXG™ 4K

EXCLUSIVELY FROM GATES

3/4"